



72095-00001.A


i

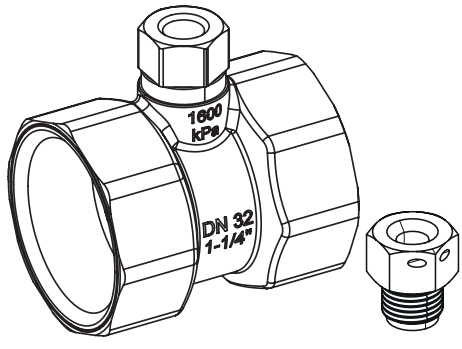


	DN	Rp	L1	L ±0.4	H
A-22PE-A01	15	1/2"	15.3	52.5	45
A-22PE-A02	20	3/4"	16.6	57.1	42.5
A-22PE-A03	25	1"	19.4	64.7	40
A-22PE-A04	32	1 1/4"	21.7	70.5	42
A-22PE-A05	40	1 1/2"	22.3	70.5	46
A-22PE-A06	50	2"	26.6	80.1	52

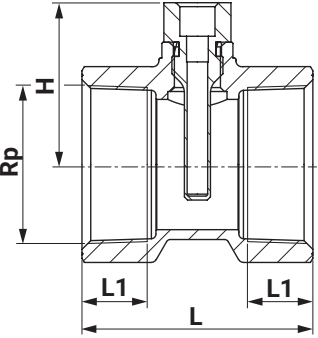

1

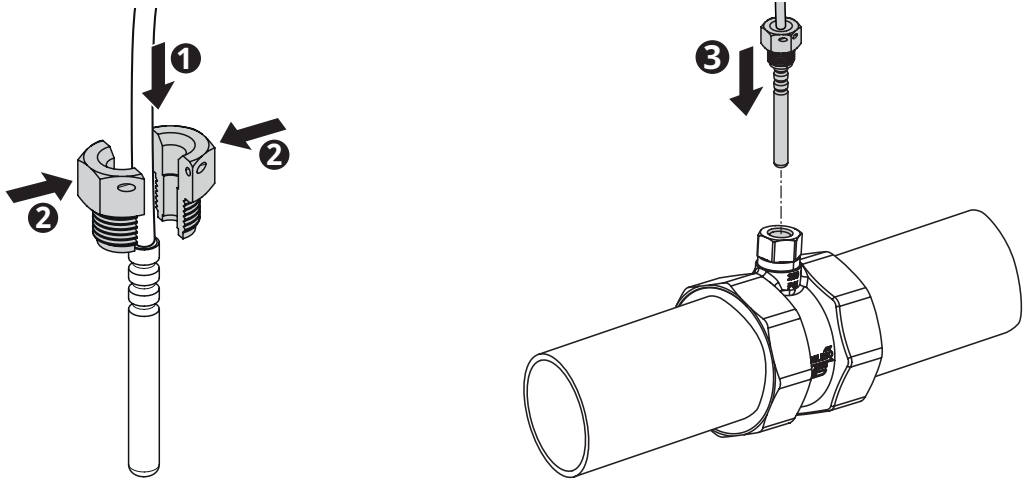

2

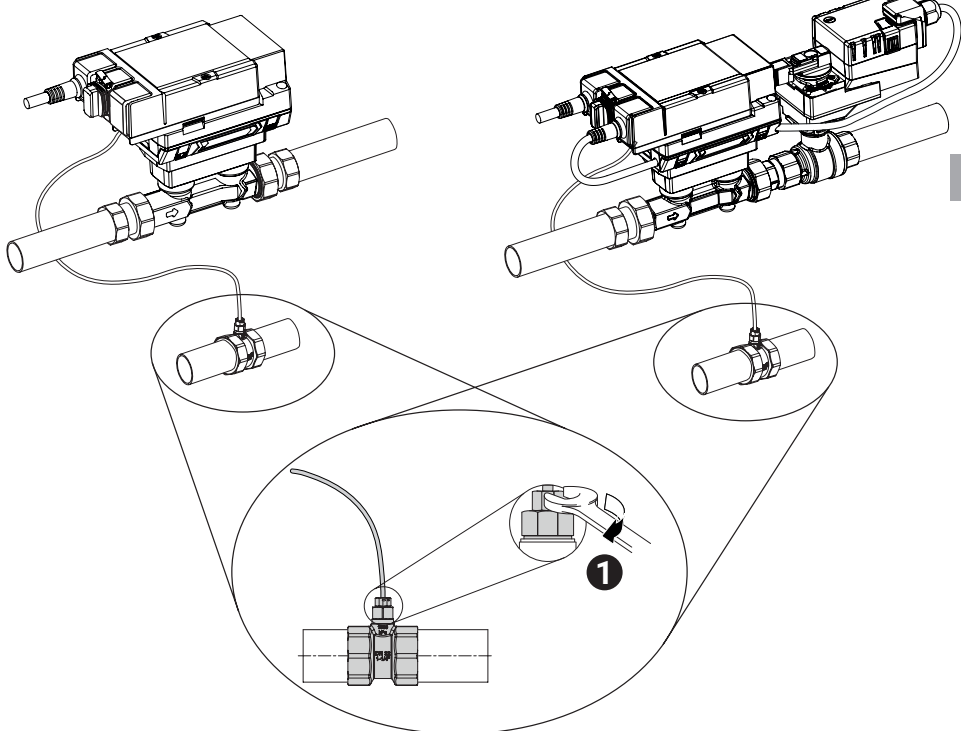

22PE-1U..

EV..R2+BAC

