




3



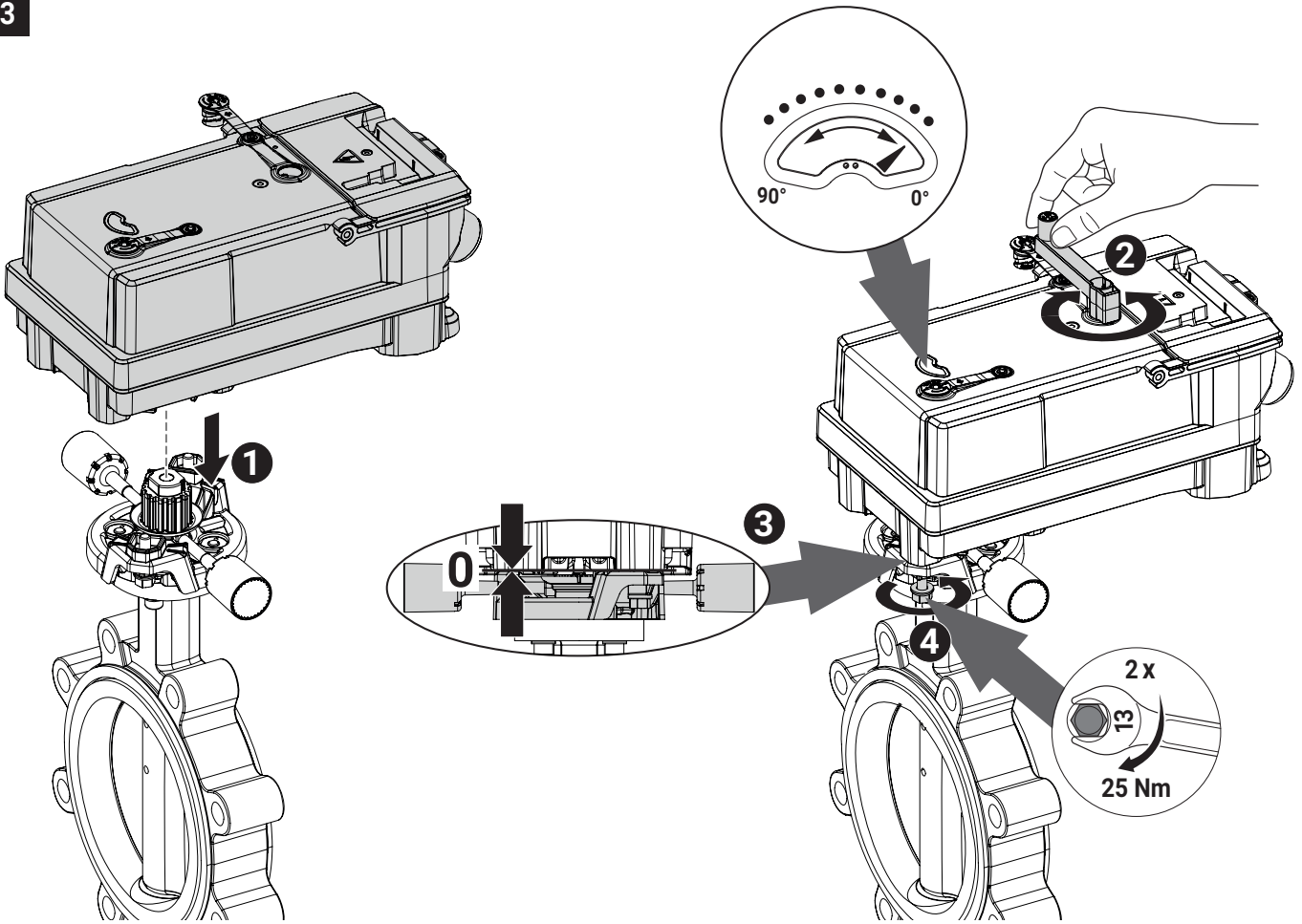



4

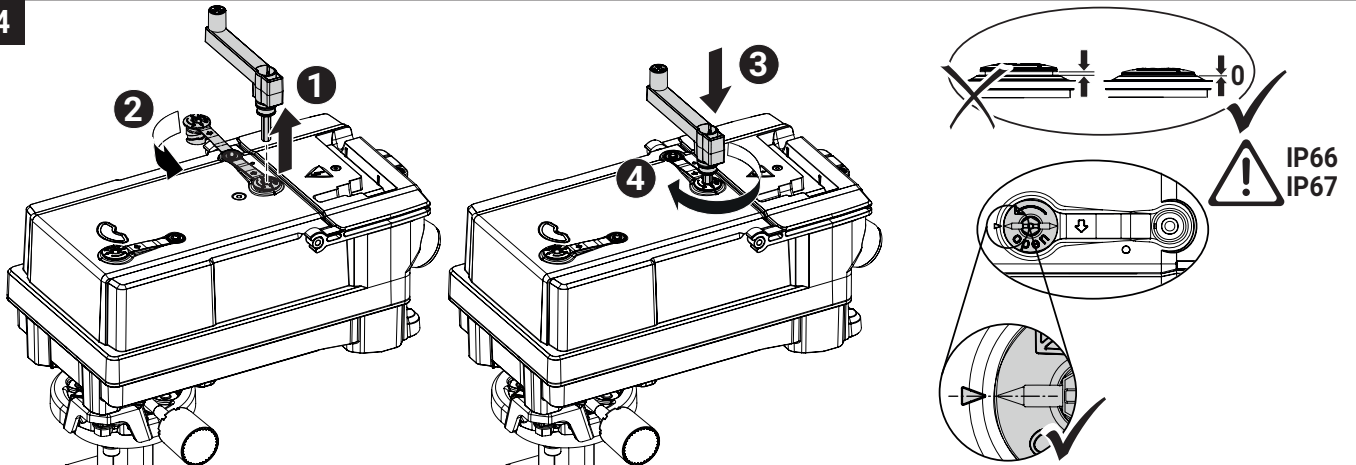


i

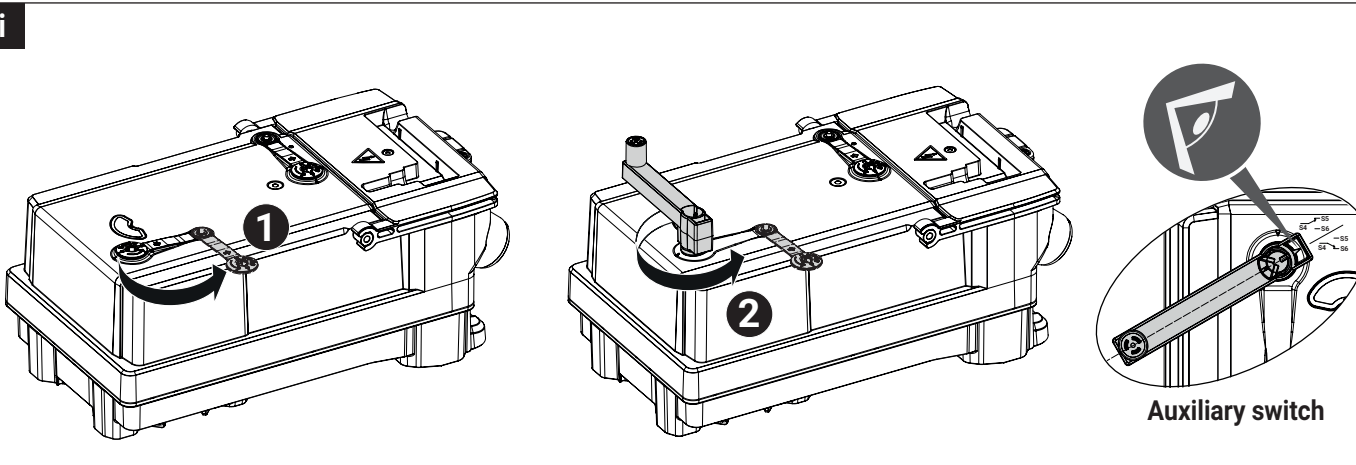

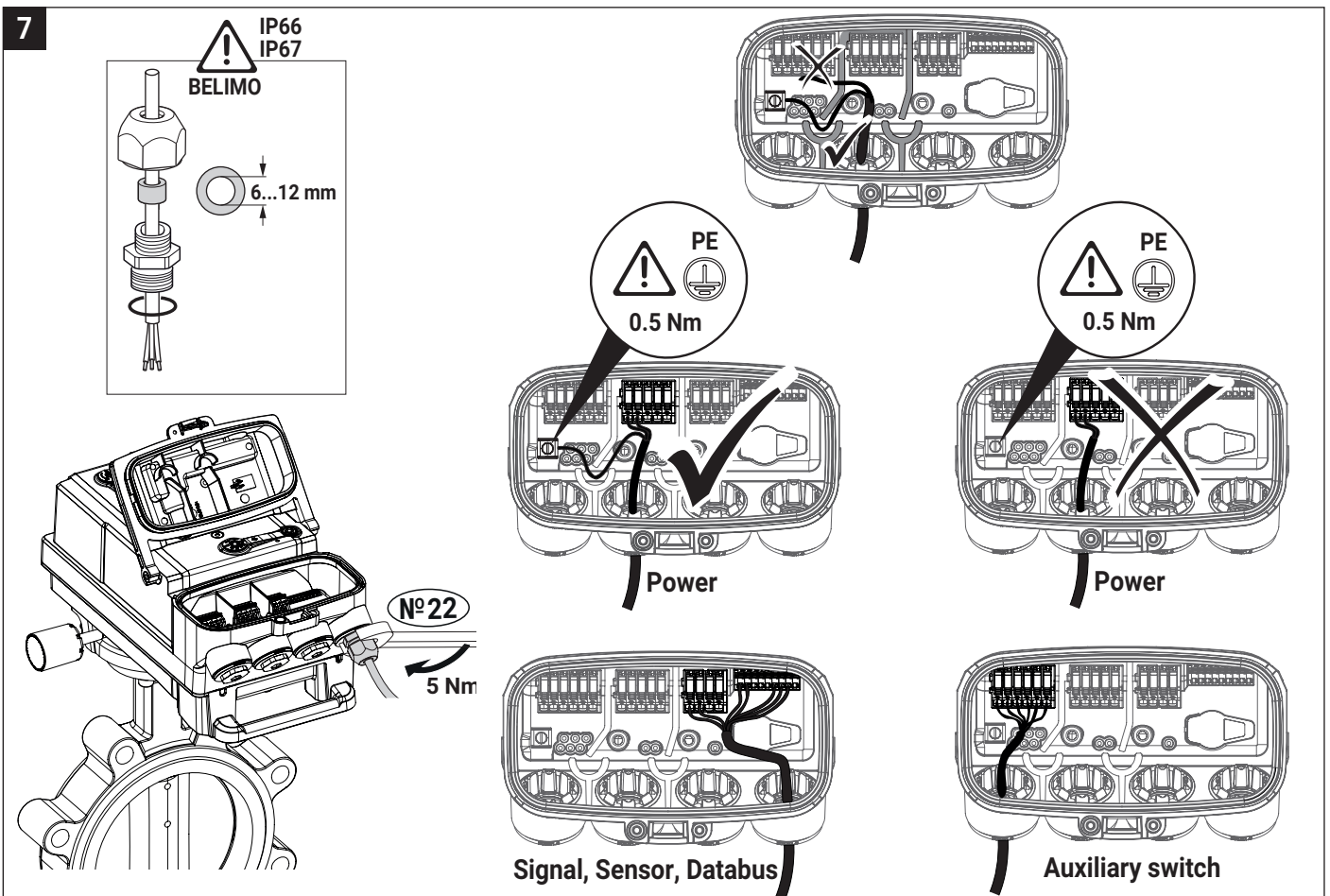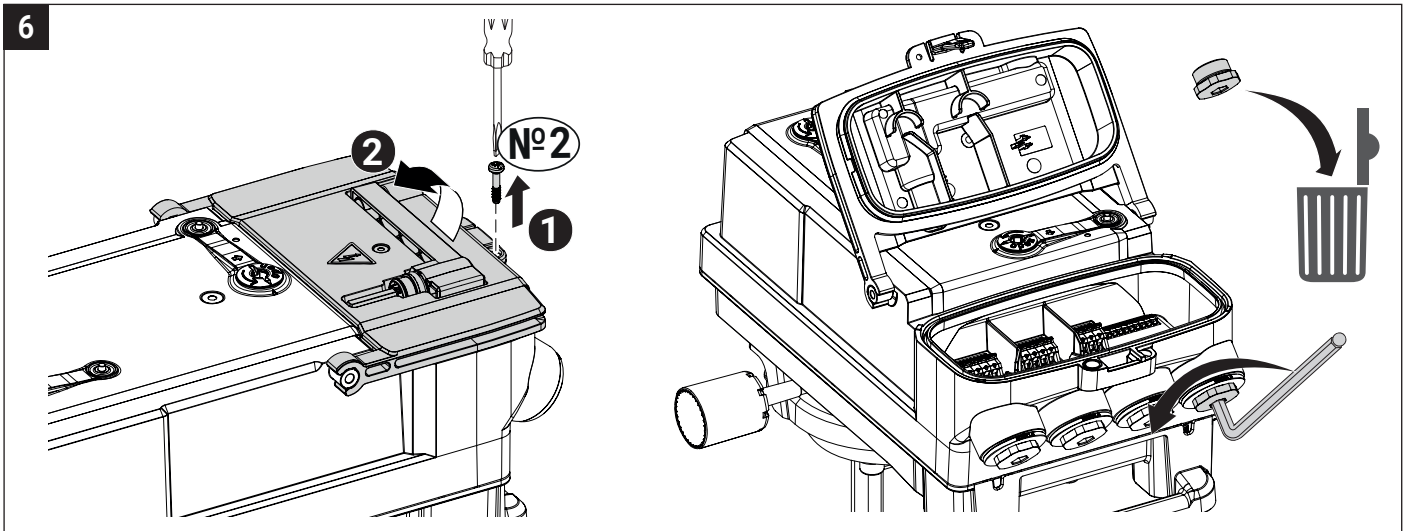
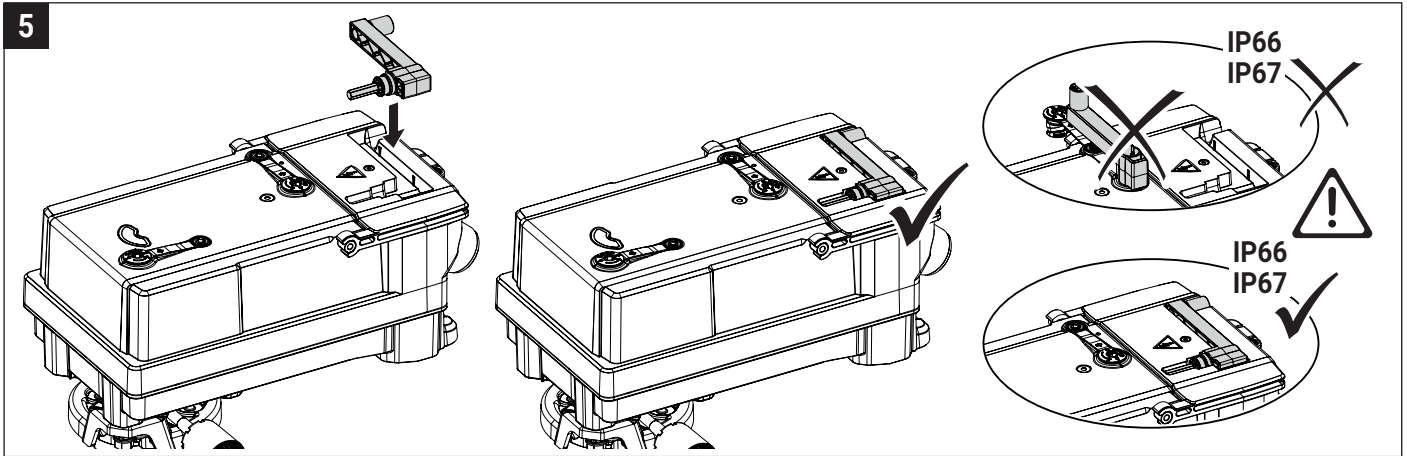


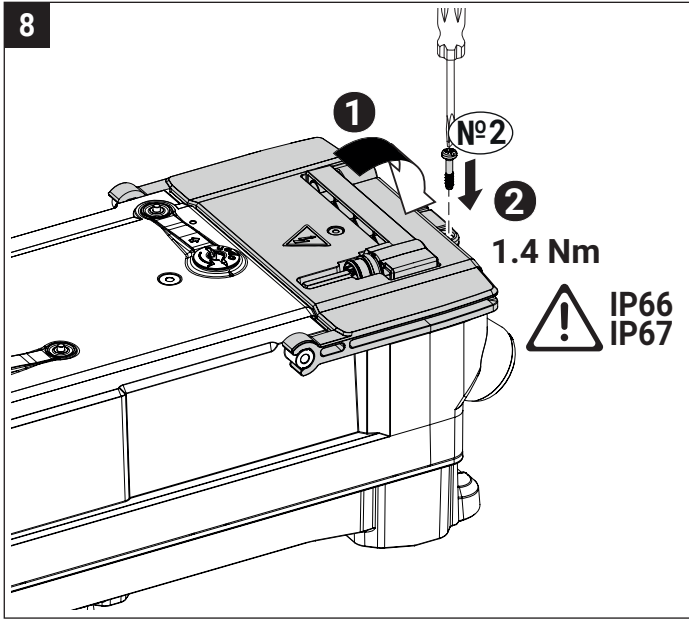


AC 24...240 V ⚠
DC 24...125 V ⚠

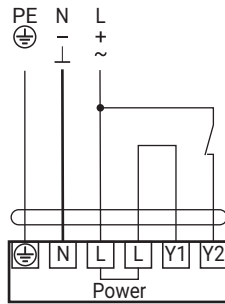

JRCA-S2-T
JR(K)CA-BAC-S2-T

 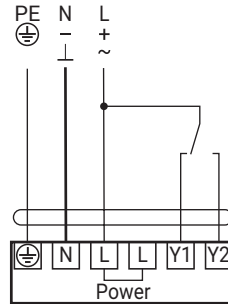

AC 24...240 V ⚠
DC 24...125 V ⚠

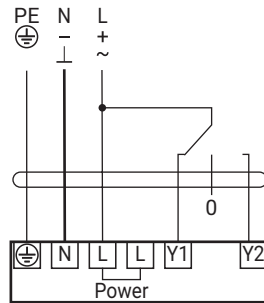



JRCA-S2-T
JR(K)CA-BAC-S2-T

Connection auxiliary switch


230 V + 230 V ✓
24 V + 24 V ✓

 ~~230 V + 24 V~~
~~24 V + 230 V~~

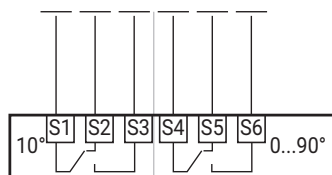




AC 24...240 V
DC 24...125 V

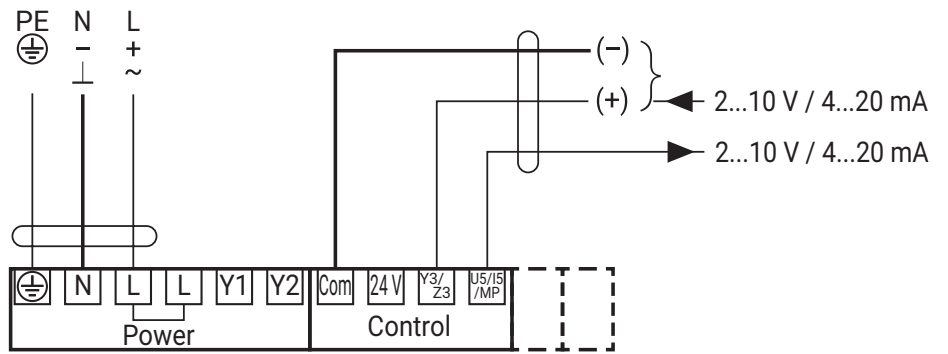


JR(K)CA-BAC-S2-T

MP-Bus

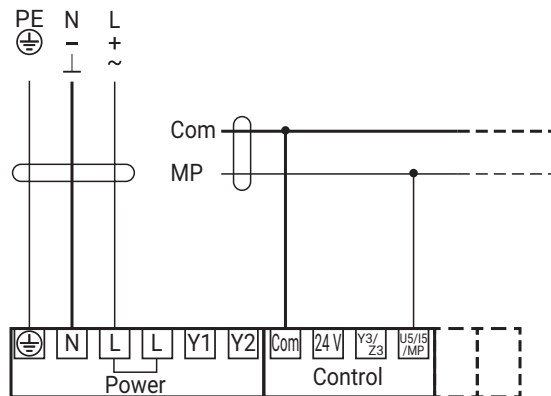

BACnet MS/TP / Modbus RTU

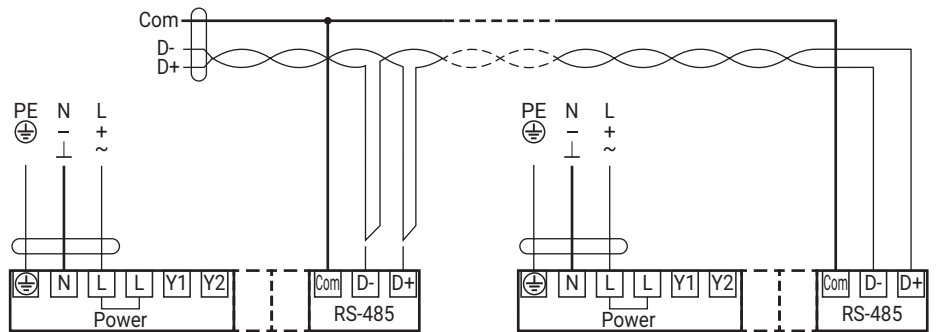

BACnet MS/TP / Modbus RTU / analog

