



R6..AS Dimensions

70731-00001.C


Valve type	Valve size	L (mm)	L1 (mm)	H (mm)	H1 (mm)	ΦD (mm)	ΦC (mm)	Φg (mm)	t (mm)	Φh (mm)	N	Weight (kg)
R610AS-R614AS	DN15	108	50	222	75	95	65	46	16	14	4	6.6
R623AS-R624AS	DN25	127	60	237	90	115	85	65	18	14	4	8.6
R638AS-R639AS	DN40	165	82.5	265	103	150	110	84	20	19	4	12
R649AS	DN50	178	89	269	107	165	125	99	20	19	4	13.5
R664AS	DN65	190	90	286	124	185	145	118	22	19	4	18
R679AS	DN80	203	100	287	125	200	160	132	22	19	8	20.5

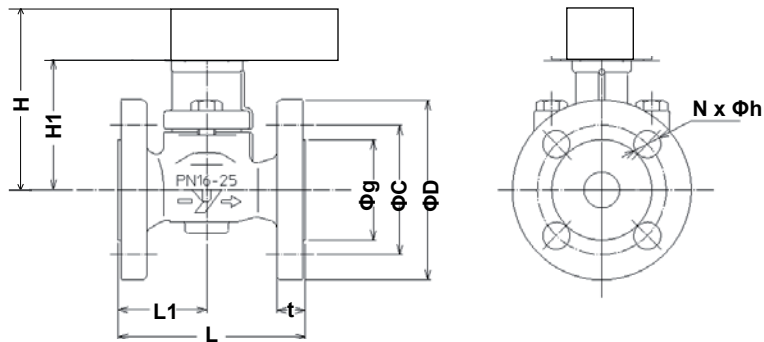

<p align="center">DN15..DN25 / LFH..</p>	<p align="center">DN40..DN80 / SRFU..</p>	
	<p align="center">Do not apply heat insulation to the actuator or linkage. Apply heat insulation only to the area boxed with dashed lines.</p>	<p align="center">Insert the bolts, tighten the bolts evenly by the cross-over method to eliminate concentrated stress.</p>

 


AC 24V / DC 24V ⚠

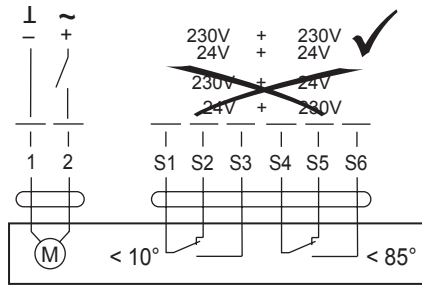


LFH24-S


AC 230V

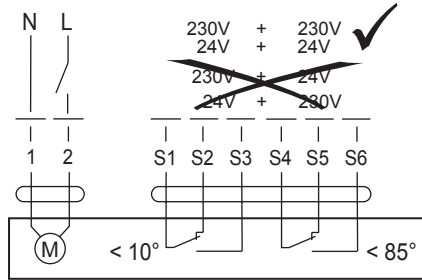


LFH230-S

 


AC 24V / DC 24V ⚠

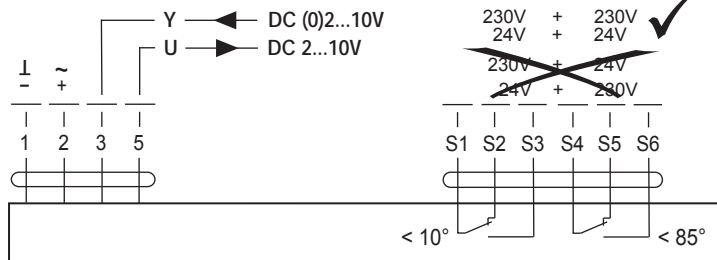

LFH24-SR-S

 



AC 24...240V
DC 24...125V ⚠

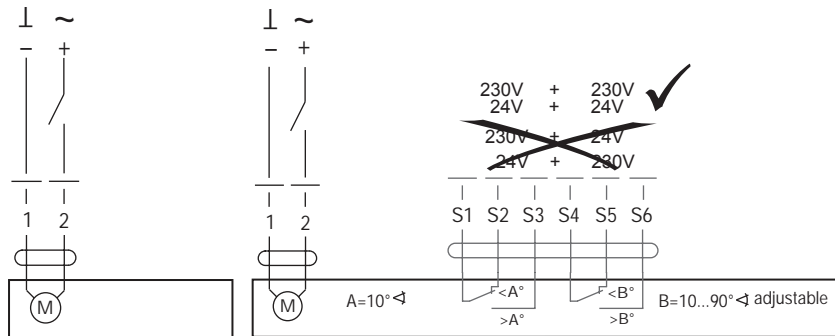


SRFU-5

SRFU-S2-5

  Auxiliary switch B



AC 24V / DC 24V ⚠

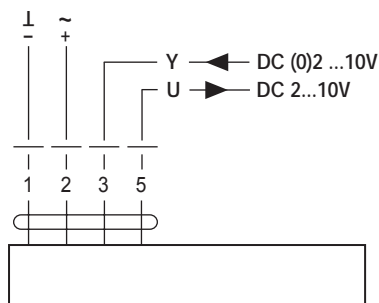

SRFU24-SR-5